


# Distributor block MS6N-FRM-FRZ

Part number: 554102

FESTO

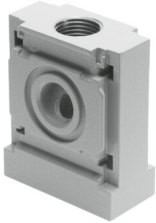

 General operating condition

## Data sheet

Feature	Value
Mounting position	Any
Structural design	Branching module
Symbol	00991510
Operating pressure	0 bar ... 20 bar
Standard nominal flow rate in main flow direction 1 -> 2	14600 l/min
Standard nominal flow rate outlet at top	10400 l/min
Standard nominal flow rate outlet down	9850 l/min
Certification	c UL us - Recognized (OL)
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4] Inert gas
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-10 °C ... 60 °C
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	163 g
Pneumatic connection 3	NPT1/2-14
Pneumatic connection 4	NPT1/2-14
Note on materials	RoHS-compliant
Housing material	Die-cast aluminum