


# Angled connection plate VABF-S2-2-A1G2-N12

Part number: 555703

FESTO

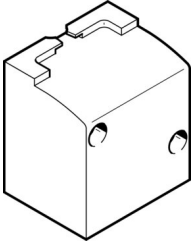

 [General operating condition](#)

## Data sheet

Feature	Value
Width	58.1 mm
Based on norm	ISO 5599-2
Mounting position	Any
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 NEMA 4
Ambient temperature	-5 °C ... 50 °C
Product weight	359 g
Type of mounting	With through-hole
Note on materials	RoHS compliant
Housing material	Wrought aluminum alloy