


Vertical pressure supply plate VABF-S1-2-P1A3-G12

FESTO

Part number: 555785

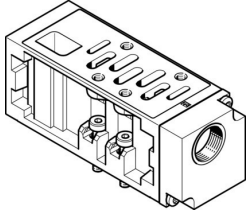

 General operating condition

Data sheet

Feature	Value
Width	54 mm
Based on norm	ISO 5599-1
Mounting position	Any
Pneumatic vertical stacking	Alternative pressure supply for 1
Symbol	00991883
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Inlet pressure 1	0.5 bar ... 10 bar
Inlet pressure 1 MPa	0.05 MPa ... 1 MPa
Inlet pressure 1 psi	7.25 psi ... 145 psi
Normal nominal flow rate (normalized to DIN 1343)	2800 l/min
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 NEMA 4
Ambient temperature	-5 °C ... 50 °C
Product weight	605 g
Vertical stacking mounting type	On manifold sub-base On individual sub-base
Pneumatic connection 1	G1/2
Note on materials	RoHS-compliant
Housing material	Die-cast aluminum