


Manifold sub-base VABV-S6-1Q-N12

Part number: 556988

FESTO

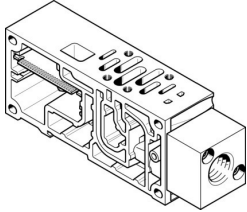

 [General operating condition](#)

Data sheet

Feature	Value
Width	43 mm
Vibration resistance	Transport application test with severity level 2 as per FN 942017-4 and EN 60068-2-6
Shock resistance	Shock test with severity level 2 as per FN 942017-5 and EN 60068-2-27
Note on forced dynamization	Switching frequency at least once a month
CE marking (see declaration of conformity)	As per EU low voltage directive
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	570 g
Pneumatic connection 1	1/2 NPT
Note on materials	RoHS-compliant
Plate material	Die-cast aluminum