


# Manifold rail MHJ10-P16

Part number: 557608

FESTO

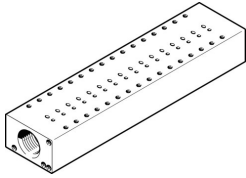

 [General operating condition](#)

## Data sheet

Feature	Value
Width dimension	11 mm
Reverse polarity protection	For operating voltage
Max. no. of valve positions	16 Versions according to customer specifications possible
Certification	RCM compliance mark
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Product weight	635 g
Type of mounting	With retaining bracket
Pneumatic connection 1	G1/2
Pneumatic connection 2	M7
Note on materials	RoHS compliant
Manifold rail material	Wrought aluminum alloy, anodized