


Manifold rail MHJ10-P16

Part number: 557608

FESTO

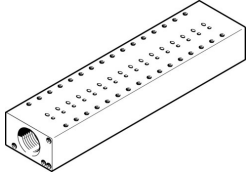

 [General operating condition](#)

Data sheet

| Feature | Value |
|----------------------------------|--|
| Width dimension | 11 mm |
| Reverse polarity protection | for operating voltage |
| Max. no. of valve positions | 16 Versions according to customer specifications possible |
| Certification | RCM compliance mark |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Product weight | 635 g |
| Type of mounting | With mounting bracket |
| Pneumatic connection 1 | G1/2 |
| Pneumatic connection 2 | M7 |
| Note on materials | RoHS-compliant |
| Manifold rail material | Wrought aluminum alloy, anodized |