


# Axial kit EAMM-A-L48-70A

Part number: 557982

FESTO

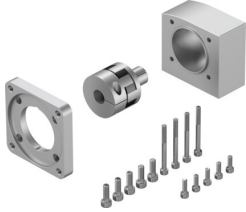

 [General operating condition](#)

## Data sheet

| Feature                  | Value                  |
|--------------------------|------------------------|
| Nominal length           | 40.2 mm                |
| Mounting position        | Any                    |
| Max. rotational speed    | 8000 rpm               |
| LABS (PWIS) conformity   | VDMA24364-B2-L         |
| Storage temperature      | -25 °C ... 60 °C       |
| Relative air humidity    | 0 - 95%                |
| Degree of protection     | IP40                   |
| Ambient temperature      | -10 °C ... 60 °C       |
| Mass moment of inertia   | 14.5 kgmm <sup>2</sup> |
| Transferable torque      | 12.5 Nm                |
| Product weight           | 350 g                  |
| Interface code, actuator | L48                    |
| Interface code, motor in | 70A                    |
| Note on materials        | RoHS compliant         |