


# End plate VABE-S6-2R-G34

Part number: 560837

FESTO

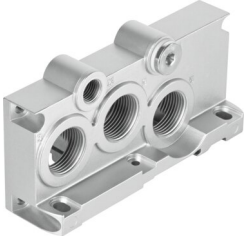

 [General operating condition](#)

## Data sheet

Feature	Value
Based on norm	ISO 5599-2
Mounting position	Any
Valve terminal type	44
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	336 g
Pilot air port 12	G1/4
Pneumatic connection 1	G3/4
Pneumatic connection 3	G3/4
Pneumatic connection 5	G3/4
Note on materials	RoHS-compliant
End plate material	Die-cast aluminum