


# Manifold sub-base VABV-S2-2S-N12-T2

Part number: 560843

FESTO

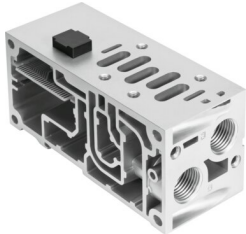

 [General operating condition](#)

## Data sheet

Feature	Value
Width dimension	59 mm
Valve terminal type	44
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
CE marking (see declaration of conformity)	As per EU low voltage directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	610 g
Pneumatic connection 2	1/2 NPT
Pneumatic connection 4	1/2 NPT
Note on materials	RoHS-compliant
Plate material	Die-cast aluminum