


End plate VMPAL-EPL-SD44

Part number: 560939

FESTO

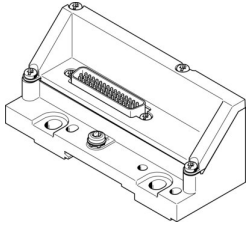

 [General operating condition](#)

Data sheet

Feature	Value
Width	43 mm
Length	107.3 mm
Max. no. of valve positions	32
Valve manifold design	Interchangeable valve sizes
Max. no. of solenoid coils	32
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Nominal operating voltage DC	24 V
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP67
Note on degree of protection	In mounted state With accessories VMPAL-KM
Ambient temperature	-5 °C ... 50 °C
Product weight	190 g
Electrical connection 1, function	Multi-pin
Electrical connection 1, connection type	Plug
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	44
Electrical connection for input 1, connection pattern	00995647
Note on materials	RoHS compliant
End plate material	Die-cast aluminum PA-reinforced