


End plate VMPAL-EPL-SD44-IP40

Part number: 560941

FESTO

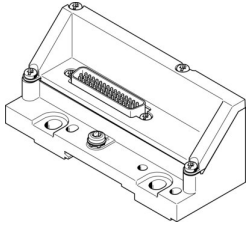

 General operating condition

Data sheet

Feature	Value
Width	43 mm
Length	107.3 mm
Max. no. of valve positions	32
Valve manifold design	Interchangeable valve sizes
Max. no. of solenoid coils	32
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Nominal operating voltage DC	24 V
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP40
Note on degree of protection	In mounted state
Ambient temperature	-5 °C ... 50 °C
Product weight	190 g
Electrical connection 1, function	Multi-pin
Electrical connection 1, connection type	Plug
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	44
Electrical connection for input 1, connection pattern	00995647
Note on materials	RoHS compliant
End plate material	Die-cast aluminum PA-reinforced