


# End plate VMPAL-EPR-SP

Part number: 560947

FESTO

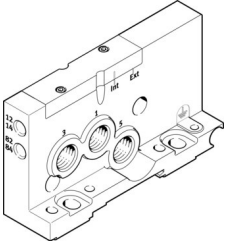

 General operating condition

## Data sheet

Feature	Value
Width	28.8 mm
Length	107.3 mm
Integrated function	Coding cover for determining the control air supply (internal or external)
Flow direction	Reversible
Valve manifold design	Interchangeable valve sizes
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Pilot pressure MPa	0.3 MPa ... 0.8 MPa
Pilot pressure	3 bar ... 8 bar
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 IP67
Note on degree of protection	In mounted state
Ambient temperature	-5 °C ... 50 °C
Product weight	180 g
Pilot air port 12/14	M7
Pilot exhaust air port 82/84	M7
Pneumatic connection 1	G1/4
Pneumatic connection 3	G1/4
Pneumatic connection 5	G1/4
Note on materials	RoHS compliant
End plate material	Die-cast aluminum PA-reinforced