


# Electrical manifold module VMPAL-EVAP-10-1-4

Part number: 560967

FESTO

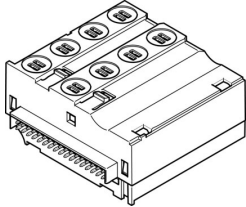

 [General operating condition](#)

## Data sheet

Feature	Value
Valve size	10 mm
Max. no. of valve positions	4
Max. no. of solenoid coils	4
Integrated function	Valve function assignment color-coded
Nominal operating voltage DC	24 V
Corrosion resistance class (CRC)	3 - High corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C ... 50 °C
Product weight	29 g
Housing colour	Gray
Housing material	PA
Note on materials	RoHS-compliant