
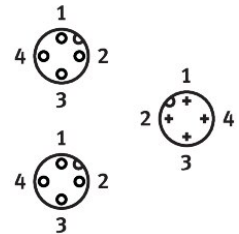


Push-in T-connector NEDU-M12D4-M12T4-IS

Part number: 562248

FESTO

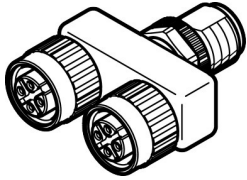

General operating condition

Data sheet

Feature	Value
Based on norm	EN 61076-2-101
Explosion prevention and protection	Observe the information on the certificate Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Contact durability	100
Type of mounting	Screw-in
Product weight	25.5 g
Electrical connection	4-pin/4-pin/4-pin A-coded/A-coded/A-coded Socket / Socket / Plug M12x1 / M12x1 / M12x1
Symbol	00992230
DC operating voltage range	0 V ... 30 V
Degree of protection	IP65 IP67
Ambient temperature	-25 °C ... 85 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS compliant
Corrosion resistance class (CRC)	3 - High corrosion stress
Housing material	TPE-U(PU)-reinforced Die-cast zinc
Material of union nut	PA-reinforced
Seals material	FPM
Material of pin contacts	Copper alloy Gold-plated