


# Axial kit EAMM-A-P4-28B-42A

Part number: 562636

FESTO

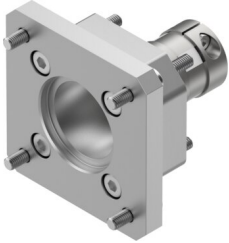

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	16.5 mm
Mounting position	Any
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	0.28 kgmm <sup>2</sup>
Transferable torque	0.7 Nm
Product weight	60 g
Interface code, actuator	P4-28B
Interface code, motor in	42A
Interface code, coupling housing	28B
Note on materials	RoHS compliant