


# Connecting cable NEBV-S1G44-K-2.5-N-LE39

Part number: 565289

FESTO

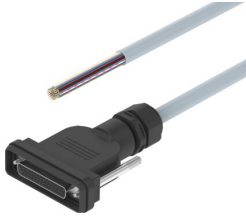

 [General operating condition](#)

## Data sheet

Feature	Value
Type of mounting	4-40UNC
Mounting position	Any
Product weight	389 g
Electrical connection	44-pin Socket Sub-D
DC operating voltage range	≤30 V
Current rating at 40° C	0.86 A
Cable length	2.5 m
Cable characteristic	For static applications
Min. cable bending radius	95 mm
Cable diameter	9.6 mm
Cable diameter tolerance	± 0.5 mm
Cable design	40 x 0.14 mm <sup>2</sup>
Degree of protection	IP65 IP67 In mounted state
Ambient temperature	-5 °C ... 60 °C
CE marking (see declaration of conformity)	As per EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
LABS (PWIS) conformity	VDMA24364-B2-L
Note on materials	RoHS compliant
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Material of cable sheath	PVC
Housing material	PBT
Material of pin contacts	Bronze Gold-plated