


Electrical sub-base VAVE-L1-1S2-LR

Part number: 566720

FESTO

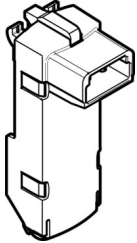

 [General operating condition](#)

Data sheet

Feature	Value
Reverse polarity protection	for operating voltage
Additional functions	Spark suppression Holding current reduction
Signal status display	LED
Nominal operating voltage DC	24 V
Surge resistance	0.8 kV
Contamination level	3
Certification	RCM compliance mark
CE marking (see declaration of conformity)	As per EU EMC directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP40
Ambient temperature	-5 °C ... 60 °C
Mounting position	Any
Product weight	1.5 g
Electrical connection	2-pin Socket
Protective earth connection	Not available
Type of mounting	Clip
Housing colour	Black
Note on materials	RoHS-compliant
Housing material	PA