


Gripper jaw blank BUB-HGPL-63

Part number: 567830

FESTO

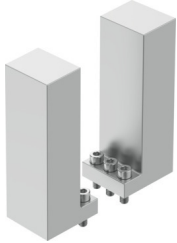

Data sheet

 [General operating condition](#)

Feature	Value
Size	63
Mounting position	Any
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	5 °C ... 60 °C
Product weight per gripper jaw	1960 g
Type of mounting	Via through-hole and centering sleeve
Note on materials	RoHS compliant
Blank material	Wrought aluminum alloy