


End plate VMPAL-EPL-SD9-IP40

Part number: 570777

FESTO

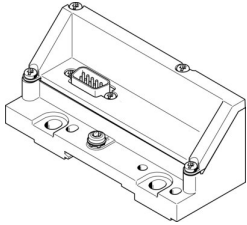

 General operating condition

Data sheet

| Feature | Value |
|---|------------------------------------|
| Width | 43 mm |
| Length | 107.3 mm |
| Max. no. of valve positions | 8 |
| Valve manifold design | Interchangeable valve sizes |
| Max. no. of solenoid coils | 8 |
| Operating pressure | -0.09 MPa ... 1 MPa |
| Operating pressure | -0.9 bar ... 10 bar |
| Pilot pressure MPa | 0.3 MPa ... 0.8 MPa |
| Pilot pressure | 3 bar ... 8 bar |
| Nominal operating voltage DC | 24 V |
| Corrosion resistance class (CRC) | 3 - High corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Degree of protection | IP40 |
| Note on degree of protection | In mounted state |
| Ambient temperature | -5 °C ... 50 °C |
| Product weight | 190 g |
| Electrical connection 1, function | Multi-pin |
| Electrical connection 1, connection type | Plug |
| Electrical connection 1, connection technology | Sub-D |
| Electrical connection 1, number of pins/wires | 9 |
| Electrical connection for input 1, connection pattern | 00995639 |
| Note on materials | RoHS compliant |
| End plate material | Die-cast aluminum PA-reinforced |