


Push-in T-fitting QBMTL-10-32-UNF-5/32-U

Part number: 572296

FESTO

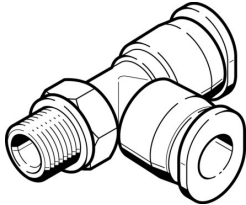

 General operating condition

Data sheet

Feature	Value
Size	Mini
Nominal width	2.489 mm
Type of seal on screwed plug	Sealing ring
Mounting position	Any
Design	L-shape, additional push-in connector, lengthwise
Pack size	10
Structural design	Push-pull principle
Operating pressure for entire temperature range	-0.095 MPa ... 1 MPa
Operating pressure for entire temperature range	-0.95 bar ... 10 bar
Operating pressure for entire temperature range	-13.775 psi ... 145 psi
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Lubricated operation possible
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364 Zone III
Ambient temperature	0 °C ... 60 °C
Max. tightening torque	1.5 Nm
Product weight	4.99 g
Type of mounting	External hexagon 5/16
Pneumatic connection 1	External thread 10-32 UNF-2A
Pneumatic connection 2	for pneumatic tubing outside diameter 5/32"
Ambient temperature Fahrenheit	32 °F ... 140 °F
Releasing ring color	Gray
Note on materials	RoHS compliant
Housing material	PBT
Releasing ring material	POM
Material of tubing seal	NBR
Material of tube retaining claw	high-alloy stainless steel