


# Fixed flow restrictor-SET VMPA1-FT-NW0.3-1.7

Part number: 572543

FESTO

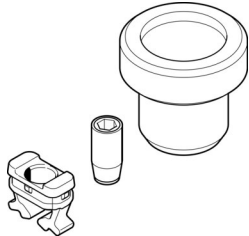

 General operating condition

## Data sheet

| Feature  | Value  |
|--|--|
| Valve function                                       | Flow control function  |
| Pneumatic connection 1                               | Sub-base   |
| Type of mounting                                     | Clamped  |
| Standard nominal flow rate in flow control direction | 3.5 l/min ... 115 l/min  |
| Operating pressure                                   | -0.009 MPa ... 0.1 MPa   |
| Operating pressure                                   | -0.09 bar ... 1 bar  |
| Ambient temperature                                  | -5 °C ... 60 °C  |
| Size   | 10   |
| Nominal width  | 0.3 mm ... 1.7 mm  |
| Mounting position                                    | Any  |
| Pack size  | 2  |
| Operating medium                                     | Compressed air as per ISO 8573-1:2010 [7:4:4]                      |
| Information on operating and pilot media             | Operation with oil lubrication possible (required for further use) |
| LABS (PWIS) conformity                               | VDMA24364-B1/B2-L  |
| Storage temperature                                  | -20 °C ... 40 °C   |
| Temperature of medium                                | -5 °C ... 60 °C  |
| Product weight                                       | 0.6 g  |
| Note on materials                                    | RoHS compliant   |
| Retainer bracket material                            | POM  |
| Hollow bolt material                                 | Wrought aluminum alloy   |