


# Adapter VMPAL-F20-G1/4

Part number: 573914

FESTO

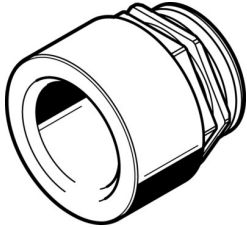

 [General operating condition](#)

## Data sheet

Feature	Value
Pack size	10
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Operating pressure	-13.05 psi ... 145 psi
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C ... 50 °C
Product weight	55 g
Pneumatic connection 1	Cartridge 18 mm
Pneumatic connection 2	G1/4
Note on materials	RoHS-compliant
Housing material	Wrought aluminum alloy