


Vertical pressure supply plate VABF-L1-P3A3-M7

Part number: 574592

FESTO

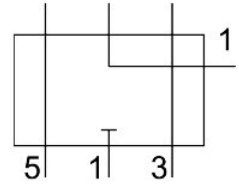

 General operating condition

Data sheet

Feature	Value
Width dimension	10.5 mm
Max. no. of valve positions	1
Symbol	00995306
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Certification	RCM compliance mark c UL us - Recognized (OL)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque for valve mounting	0.45 Nm
Product weight	220 g
Pneumatic connection 1	M7
Note on materials	RoHS-compliant
Plate material	Wrought aluminum alloy