


Vertical pressure exhaust plate VABF-L1-P7A13-G18

FESTO

Part number: 574595

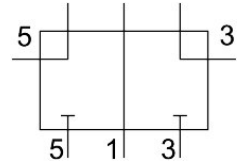

[PDF](#) General operating condition

Data sheet

Feature	Value
Width dimension	16 mm
Max. no. of valve positions	1
Symbol	00995307
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Certification	RCM compliance mark c UL us - Recognized (OL)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque for valve mounting	0.65 Nm
Product weight	350 g
Pneumatic connection 3	G1/8
Pneumatic connection 5	G1/8
Note on materials	RoHS-compliant
Plate material	Wrought aluminum alloy