


# Sub-base VMPAC-AP-14-SP-2

Part number: 576577

FESTO

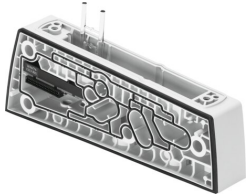

 [General operating condition](#)

## Data sheet

Feature	Value
Width	32.8 mm
Length	169 mm
Width dimension	26.8 mm
Max. no. of valve positions	1
Operating pressure	-0.9 bar ... 8 bar
Pilot pressure	3 bar ... 8 bar
Corrosion resistance class (CRC)	4 - Particularly high corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-5 °C ... 50 °C
Product weight	160 g
Pneumatic connection 1	G1/4
Pneumatic connection 2	G1/4
Pneumatic connection 3	G1/4
Pneumatic connection 4	G1/4
Pneumatic connection 5	G1/4
Note on materials	RoHS-compliant
Housing material	PA-reinforced