


# Rod clevis SG-M10X1,25

Part number: 6144

FESTO

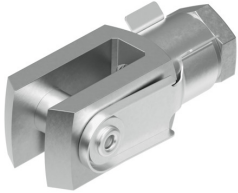

 [General operating condition](#)

## Data sheet

Feature	Value
Size	M10x1.25
Conforms to standard	ISO 8140
Threaded connection	Internal thread M10x1.25
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 1% by mass of copper are excluded from use. Circuit boards, lines, electrical push-in connectors and coils are excluded
Ambient temperature	-40 °C ... 150 °C
Max. load capacity	0.9 kN
Product weight	103 g
Note on materials	RoHS-compliant
Bolt material	Steel Galvanized
Clevis material	Steel Galvanized
Nut material	Steel Galvanized