


# Elbow quick connector GCK-1/4-PK-4-KU

Part number: 6269

FESTO

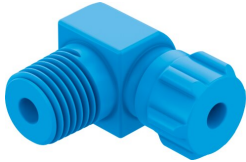

 General operating condition

## Data sheet

Feature	Value
Nominal width	2.9 mm
Mounting position	Any
Design	L-shape
Pack size	10
Operating pressure for entire temperature range	-0.095 MPa ... 1 MPa
Operating pressure for entire temperature range	-0.95 bar ... 10 bar
Operating pressure for entire temperature range	-13.775 psi ... 145 psi
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Pneumatic connection 1	External thread R1/4
Pneumatic connection 2	for pneumatic tubing outside diameter 6 mm for barbed fitting, inside diameter 4 mm, with nut
Material of union nut	POM
Material of screwed plug	POM
Note on materials	RoHS-compliant