


# AND gate ZK-1/8-B

Part number: 6680

FESTO

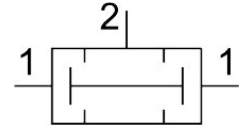

[PDF](#) General operating condition

## Data sheet

Feature	Value
Valve function	AND function
Pneumatic connection 1	G1/8
Pneumatic connection 2	G1/8
Type of mounting	With through-hole
Normal nominal flow rate (normalized to DIN 1343)	550 l/min
Operating pressure	1 bar ... 10 bar
Ambient temperature	-10 °C ... 60 °C
Housing material	Anodized
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Nominal width	4.5 mm
Mounting position	Any
Symbol	00991461
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Temperature of medium	-10 °C ... 60 °C
Product weight	45 g
Pneumatic connection 3	G1/8
Note on materials	RoHS compliant
Seals material	NBR