
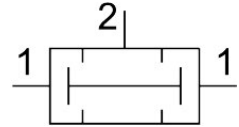


AND gate ZK-PK-3

Part number: 6685

FESTO

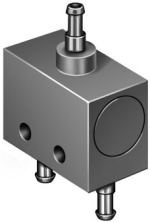

 [General operating condition](#)

Data sheet

Feature	Value
Valve function	AND function
Pneumatic connection 1	PK-3
Pneumatic connection 2	PK-3
Type of mounting	With through-hole
Normal nominal flow rate (normalized to DIN 1343)	120 l/min
Operating pressure	1.6 bar ... 8 bar
Ambient temperature	-10 °C ... 60 °C
Housing material	POM
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Nominal width	2.4 mm
Mounting position	Any
Symbol	00991461
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Temperature of medium	-10 °C ... 60 °C
Product weight	10 g
Pneumatic connection 3	PK-3
Note on materials	RoHS-compliant
Seals material	NBR