


Stem actuated micro valve S-3-PK-3-B

Part number: 7843

FESTO

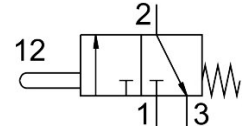

[PDF](#) General operating condition

Data sheet

Feature	Value
Valve function	3/2-way, closed, monostable
Actuation type	Mechanical
Normal nominal flow rate (normalized to DIN 1343)	60 l/min
Pneumatic working port	PK-3
Operating pressure	-0.95 bar ... 8 bar
Structural design	Poppet valve with spring return
Reset method	Mechanical spring
Nominal width	1.8 mm
Sealing principle	Soft
Mounting position	Any
Type of control	directly
Symbol	00991095
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Actuating force	6 N
Product weight	7 g
Type of mounting	With through-hole
Pneumatic connection 1	PK-3
Pneumatic connection 2	PK-3
Housing material	Polymer Brass