
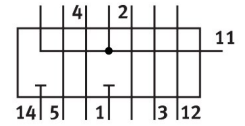


# Vertical pressure supply plate VABF-S4-1-P1A14-N14

FESTO

Part number: 8000690

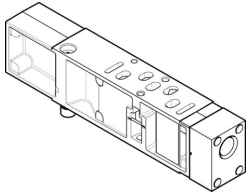

 General operating condition

## Data sheet

Feature	Value
Width	26 mm
Based on norm	ISO 15407-2
Mounting position	Any
Pneumatic vertical stacking	Alternative pressure supply for 1 and 14
Symbol	00992919
Operating pressure	1 MPa
Operating pressure	10 bar
Normal nominal flow rate (normalized to DIN 1343)	900 l/min
CE marking (see declaration of conformity)	As per EU low voltage directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 NEMA 4
Ambient temperature	-5 °C ... 50 °C
Product weight	191 g
Vertical stacking mounting type	On manifold sub-base On individual sub-base
Pneumatic connection 1	1/4 NPT
Note on materials	RoHS-compliant
Housing material	Die-cast aluminum