


Vertical pressure shut-off plate VABF-S4-2-L1D2-C

FESTO

Part number: 8001178

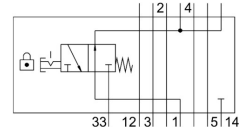

[PDF](#) [General operating condition](#)

Data sheet

Feature	Value
Width	18 mm
Based on norm	ISO 15407-2
Mounting position	Any
Symbol	00995593
Operating pressure	1 MPa
Operating pressure	10 bar
CE marking (see declaration of conformity)	As per EU low voltage directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 NEMA 4
Pilot medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Ambient temperature	-5 °C ... 50 °C
Product weight	231 g
Vertical stacking mounting type	On manifold sub-base On individual sub-base
Note on materials	RoHS-compliant
Housing material	Die-cast aluminum