


Linear gantry EXCT-30- -

Part number: 8026576

FESTO

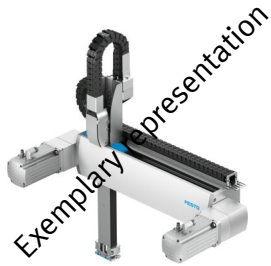

 [General operating condition](#)

Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Size	30
Mounting position	Vertical
Structural design	Linear gantry
Operating pressure	-0.95 bar ... 8 bar
Max. acceleration	50 m/s ²
Max. speed	5 m/s
Repetition accuracy	±0.1 mm
Duty cycle	100%
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-10 °C ... 60 °C
Relative air humidity	0 - 90 %
Noise level	78 dB(A)
Degree of protection	IP40
Ambient temperature	10 °C ... 40 °C
Max. process force in Z direction	300 N
Rated load with maximum dynamic response	3 kg
Type of mounting	With mounting kit With slot nuts
Note on materials	RoHS-compliant