


# Vertical pressure supply plate VMPA2-VSP-QS8

Part number: 8029488

FESTO

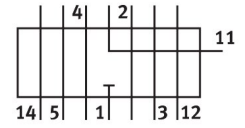

 General operating condition

## Data sheet

| Feature                          | Value   |
|----------------------------------|---|
| Width dimension                  | 21 mm   |
| Symbol                           | 00991883                                      |
| Operating pressure               | -0.09 MPa ... 1 MPa                           |
| Operating pressure               | -0.9 bar ... 10 bar                           |
| Pilot pressure MPa               | 0.3 MPa ... 0.8 MPa                           |
| Pilot pressure                   | 3 bar ... 8 bar                               |
| Operating medium                 | Compressed air as per ISO 8573-1:2010 [7:4:4] |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress                      |
| LABS (PWIS) conformity           | VDMA24364-B1/B2-L                             |
| Ambient temperature              | -5 °C ... 50 °C                               |
| Product weight                   | 85 g  |
| Pneumatic connection 1           | QS-8  |
| Note on materials                | RoHS compliant                                |
| Supply plate material            | PA-reinforced                                 |