


# Y-fitting NPFC-Y-R38-2G38-MFF

Part number: 8030233

FESTO

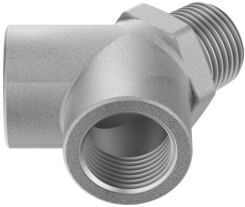

 [General operating condition](#)

## Data sheet

Feature	Value
Threaded fitting material	Brass, nickel-plated
Pack size	10
Operating pressure	-0.95 bar ... 50 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [:-:-]
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-20 °C ... 150 °C
Product weight	86.7 g
Pneumatic connection 1	R3/8
Pneumatic connection 2	G3/8
Note on materials	RoHS-compliant