


End plate VABE-S1-2LZ-N34

Part number: 8032665

FESTO

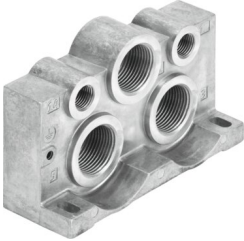

 [General operating condition](#)

Data sheet

Feature	Value
Width	44 mm
Exhaust air function	With flow control option
Based on norm	ISO 5599-1
Operating pressure	-0.09 MPa ... 1.6 MPa
Operating pressure	-0.9 bar ... 16 bar
Suitability for vacuum	yes
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C ... 60 °C
Temperature of medium	-10 °C ... 50 °C
Pilot medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Ambient temperature	-10 °C ... 50 °C
Product weight	360 g
Type of mounting	with through-hole for M6 screw
Pilot air port 12/14	1/4 NPT
Pneumatic connection 1	3/4 NPT
Pneumatic connection 3	3/4 NPT
Pneumatic connection 5	3/4 NPT
Note on materials	RoHS-compliant
End plate material	Die-cast aluminum