


# End plate VABE-S1-2L-G34

Part number: 8032666

FESTO

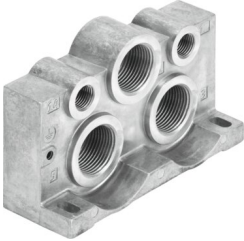

 General operating condition

## Data sheet

| Feature                                  | Value  |
|--|--|
| Width                                    | 44 mm  |
| Exhaust air function                     | Adjustable   |
| Based on norm                            | ISO 5599-1   |
| Operating pressure                       | -0.09 MPa ... 1.6 MPa  |
| Operating pressure                       | -0.9 bar ... 16 bar  |
| Suitability for vacuum                   | Yes  |
| Operating medium                         | Compressed air as per ISO 8573-1:2010 [7:4:4]                      |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC)         | 0 - No corrosion stress  |
| LABS (PWIS) conformity                   | VDMA24364-B1/B2-L  |
| Storage temperature                      | -20 °C ... 60 °C   |
| Temperature of medium                    | -10 °C ... 50 °C   |
| Pilot medium                             | Compressed air as per ISO 8573-1:2010 [7:4:4]                      |
| Ambient temperature                      | -10 °C ... 50 °C   |
| Product weight                           | 360 g  |
| Type of mounting                         | with through-hole for M6 screw                                     |
| Pneumatic connection 1                   | G3/4   |
| Pneumatic connection 3                   | G3/4   |
| Pneumatic connection 5                   | G3/4   |
| Note on materials                        | RoHS compliant   |
| End plate material                       | Die-cast aluminum  |