
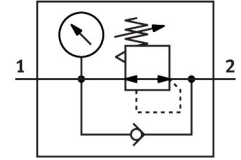


Regulator plate VMPA14-B8-R2-M5-10

Part number: 8043516

FESTO

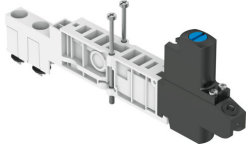

[General operating condition](#)

Data sheet

| Feature | Value |
|--|--|
| Width | 14 mm |
| Mounting position | Any |
| Pneumatic vertical stacking | Pressure regulator for 2 |
| Controller function | Outlet pressure constant With secondary exhausting |
| Symbol | 00992003 |
| Pressure regulation range | 2 bar ... 6 bar |
| Inlet pressure 1 | 0.5 bar ... 10 bar |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:4:4] |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Degree of protection | IP65 as per IEC 60529 |
| Ambient temperature | -5 °C ... 50 °C |
| Max. tightening torque | 0.65 Nm |
| Product weight | 76 g |
| Vertical stacking mounting type | On manifold sub-base |
| Pressure gauge connection | M5 |
| Note on materials | RoHS-compliant |
| Material of operator panel | PA |
| Seals material | NBR |
| Controller housing material | PA |