


Parallel kit EAMM-U-50-S38-38AA-78

Part number: 8058926

FESTO

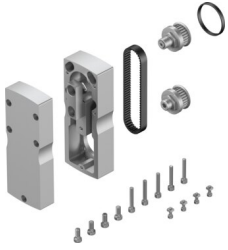

Data sheet

 [General operating condition](#)

Feature	Value
Size	50
Mounting position	Any
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	12.1 kgmm ²
No-load driving torque	0.01 Nm
Transferable torque	1 Nm
Product weight	600 g
Interface code, actuator	S38
Interface code, motor in	38AA
Note on materials	RoHS compliant