


# Axial kit EAMM-A-L27-57AC

Part number: 8063451

FESTO

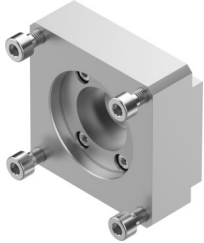

 [General operating condition](#)

## Data sheet

| Feature                  | Value                   |
|--------------------------|-------------------------|
| Nominal length           | 23.1 mm                 |
| Mounting position        | Any                     |
| Max. rotational speed    | 10000 rpm               |
| LABS (PWIS) conformity   | VDMA24364-B2-L          |
| Storage temperature      | -25 °C ... 60 °C        |
| Relative air humidity    | 0 - 95%                 |
| Degree of protection     | IP40                    |
| Ambient temperature      | -10 °C ... 60 °C        |
| Mass moment of inertia   | 0.355 kgmm <sup>2</sup> |
| Transferable torque      | 2 Nm                    |
| Product weight           | 216 g                   |
| Interface code, actuator | L27                     |
| Interface code, motor in | 57AC                    |
| Note on materials        | RoHS compliant          |