


Axial kit EAMM-A-L48-75GA

Part number: 8063484

FESTO

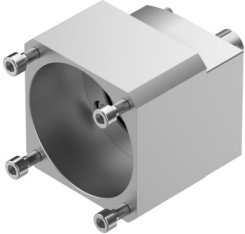

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------|----------------------|
| Nominal length | 74.4 mm |
| Mounting position | Any |
| Max. rotational speed | 6000 rpm |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Degree of protection | IP40 |
| Ambient temperature | -10 °C ... 60 °C |
| Mass moment of inertia | 39 kgmm ² |
| Transferable torque | 17 Nm |
| Product weight | 780 g |
| Interface code, actuator | L48 |
| Interface code, motor in | 75GA |
| Note on materials | RoHS-compliant |