


# Axial kit EAMM-A-M48-40G

Part number: 8063549

FESTO

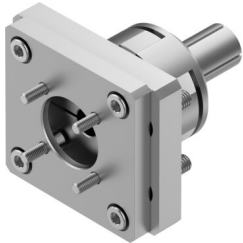

 [General operating condition](#)

## Data sheet

| Feature                  | Value                |
|--------------------------|----------------------|
| Nominal length           | 17.5 mm              |
| Mounting position        | Any                  |
| Max. rotational speed    | 6000 rpm             |
| LABS (PWIS) conformity   | VDMA24364-B2-L       |
| Storage temperature      | -25 °C ... 60 °C     |
| Relative air humidity    | 0 - 95 %             |
| Degree of protection     | IP40                 |
| Ambient temperature      | -10 °C ... 60 °C     |
| Mass moment of inertia   | 39 kgmm <sup>2</sup> |
| Transferable torque      | 17 Nm                |
| Product weight           | 433 g                |
| Interface code, actuator | M48                  |
| Interface code, motor in | 40G                  |
| Note on materials        | RoHS-compliant       |