


Axial kit EAMM-A-N38-70AA

Part number: 8063576

FESTO

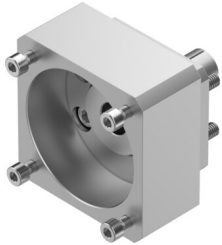

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------|------------------------|
| Nominal length | 37 mm |
| Mounting position | Any |
| Max. rotational speed | 8000 rpm |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Storage temperature | -25 °C ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Degree of protection | IP40 |
| Ambient temperature | -10 °C ... 60 °C |
| Mass moment of inertia | 14.5 kgmm ² |
| Transferable torque | 12.5 Nm |
| Product weight | 369 g |
| Interface code, actuator | N38 |
| Interface code, motor in | 70AA 70AB |
| Note on materials | RoHS-compliant |