


# Vacuum filter OAFF-G3-5

Part number: 8068944

FESTO

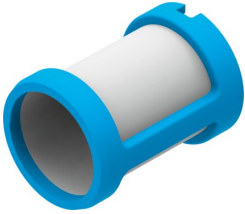

 [General operating condition](#)

## Data sheet

Feature	Value
Grade of filtration	40 µm
Pack size	10
Symbol	00991483
Operating pressure	-0.095 MPa ... 0 MPa
Operating pressure	-0.95 bar ... 0 bar
Operating pressure	-13.775 psi ... 0 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	1 g
Type of mounting	Push-on Engaging
Note on materials	RoHS-compliant
Compressed air filter material	Fabric PA
Housing material	POM
Ejector pulse suitability	0.7 MPa
Ejector pulse suitability	7 bar
Ejector pulse suitability	101.5 psi