


# Manifold rail VABM-P7-18M-G18-M5-6

Part number: 8076388

FESTO

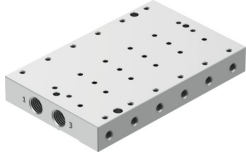

 [General operating condition](#)

## Data sheet

Feature	Value
Width dimension	18 mm
Structural design	Connection direction at side
Max. no. of valve positions	6
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Max. tightening torque for valve mounting	0.6 Nm
Product weight	270 g
Pneumatic connection 1	G1/8
Pneumatic connection 2	M5
Note on materials	RoHS-compliant
Manifold rail material	Wrought aluminum alloy