


# Axial kit EAMM-A-T42-55A

Part number: 8082614

FESTO

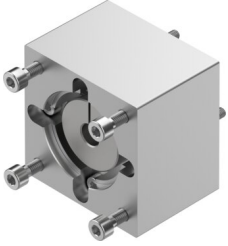

 [General operating condition](#)

## Data sheet

Feature	Value
Nominal length	43 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	3.2 kgmm <sup>2</sup>
Transferable torque	8.5 Nm
Product weight	328 g
Interface code, actuator	T42
Interface code, motor in	55A
Note on materials	RoHS compliant