


Manifold rail

VABM-P6-15M-G18-M5-6

Part number: 8083545

FESTO

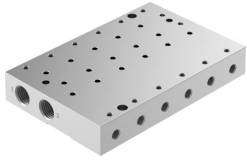

 [General operating condition](#)

Data sheet

| Feature | Value |
|---|-------------------------------|
| Width dimension | 15 mm |
| Structural design | Connection direction at side |
| Max. no. of valve positions | 6 |
| Corrosion resistance class (CRC) | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Max. tightening torque for valve mounting | 0.6 Nm |
| Product weight | 210 g |
| Pneumatic connection 1 | G1/8 |
| Pneumatic connection 2 | M5 |
| Note on materials | RoHS-compliant |
| Manifold rail material | Wrought aluminum alloy |