


Manifold rail VABM-P6-15MB-G18-M5-8

Part number: 8083548

FESTO

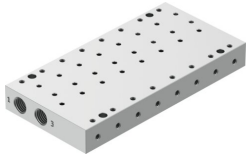

 [General operating condition](#)

Data sheet

Feature	Value
Width dimension	15 mm
Structural design	Connection direction underneath
Max. no. of valve positions	8
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Max. tightening torque for valve mounting	0.6 Nm
Product weight	280 g
Pneumatic connection 1	G1/8
Pneumatic connection 2	M5
Note on materials	RoHS compliant
Manifold rail material	Wrought aluminum alloy