


Axial kit EAMM-A-T42-60AA

Part number: 8092255

FESTO

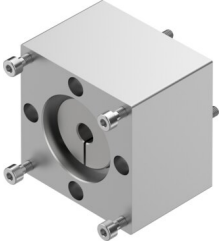

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	43 mm
Mounting position	Any
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	3.2 kgmm ²
Transferable torque	7.5 Nm
Product weight	315 g
Interface code, actuator	T42
Interface code, motor in	60AA
Note on materials	RoHS compliant