


Axial kit EAMM-A-V32-38AA

Part number: 8093023

FESTO

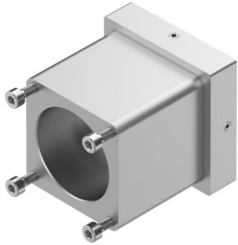

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	46 mm
Mounting position	Any
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	0.19 kgmm ²
Transferable torque	1.5 Nm
Product weight	112 g
Interface code, actuator	V32
Interface code, motor in	38AA
Note on materials	RoHS compliant